


# parallel kit EAMM-U-50-S38-38AA-78

Part number: 8058926

FESTO

Suitable for electric drives.

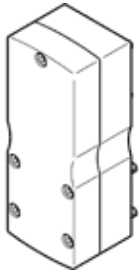

## Data sheet

Feature	Value
Size	50
Assembly position	Any
Max. speed	6,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Mass moment of inertia	12.1 kgmm <sup>2</sup>
No-load driving torque	0.01 Nm
Transferable torque	1 Nm
Product weight	600 g
Interface code, actuator	S38
Interface code, motor in	38AA
Materials note	Conforms to RoHS