


quick coupling plug NPHS-S6-M-G38

Part number: 8059259

FESTO

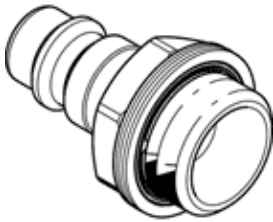

Data sheet

Feature	Value
Nominal size	7.85 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-10 ... 60 °C
Nominal tightening torque	12.5 Nm
Tolerance for nominal tightening torque	± 20 %
Product weight	27 g
Pneumatic connection, port 1	Male thread G3/8
Materials note	Conforms to RoHS