


coupling socket NPHS-D6-P-G38F

Part number: 8059272

FESTO

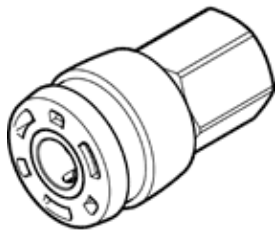

Data sheet

Feature	Value
Operating pressure complete temperature range	-0.95 ... 10 bar
Standard nominal flow rate	2,083 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-10 ... 60 °C
Product weight	114 g
Pneumatic connection, port 1	Female thread G3/8
Materials note	Conforms to RoHS