


# coupling socket NPHS-D6-M-G14

Part number: 8059275

FESTO

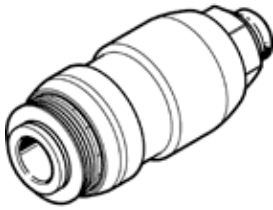

## Data sheet

Feature	Value
Nominal size	8.2 mm
Operating pressure complete temperature range	-0.95 ... 20 bar
Standard nominal flow rate	1,833 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-20 ... 80 °C
Nominal tightening torque	7 Nm
Tolerance for nominal tightening torque	± 20 %
Product weight	173 g
Pneumatic connection, port 1	Male thread G1/4
Materials note	Conforms to RoHS