


**axial kit**  
**EAMM-A-L38-60RB**  
Part number: 8063460

**FESTO**

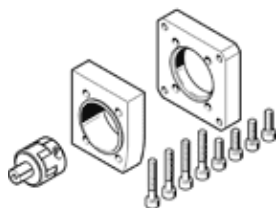

**Data sheet**

<b>Feature</b>	<b>Value</b>
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	9 Nm
Product weight	318 g
Interface code, actuator	L38
Interface code, motor in	60RB
Materials note	Conforms to RoHS