


axial kit
EAMM-A-L62-90GA
Part number: 8063505

FESTO

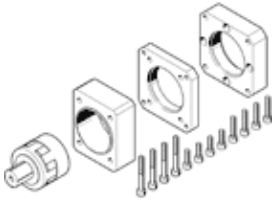

Data sheet

| Feature | Value |
|--------------------------|------------------|
| Assembly position | Any |
| PWIS conformity | VDMA24364-B2-L |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Protection class | IP40 |
| Ambient temperature | -10 ... 60 °C |
| Transferable torque | 47 Nm |
| Product weight | 1,645 g |
| Interface code, actuator | L62 |
| Interface code, motor in | 90GA |
| Materials note | Conforms to RoHS |