


# axial kit EAMM-A-N80-100A

Part number: 8063607

FESTO

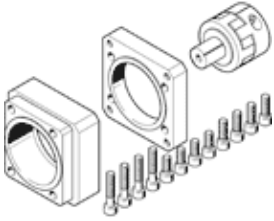

## Data sheet

Feature	Value
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	47 Nm
Product weight	1,627 g
Interface code, actuator	N80
Interface code, motor in	100A
Materials note	Conforms to RoHS