


reducing sleeve NPFC-R-G12-G38-F

Part number: 8069224

FESTO

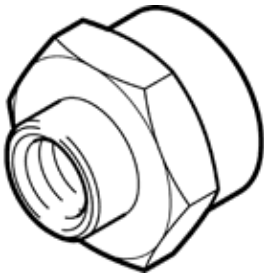

Data sheet

Feature	Value
Material threaded fitting	Nickel-plated brass
Container size	10
Operating pressure	-0.95 ... 50 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:-:-]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-20 ... 150 °C
Product weight	38 g
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	G3/8
Materials note	Conforms to RoHS