


sub-base VABS-BE-BS-G14-V14-A

Part number: 8072668
New

FESTO

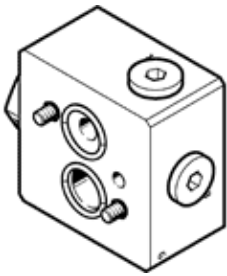

Data sheet

| Feature | Value |
|---|---|
| Assembly position | Any |
| Operating pressure MPa | 0 ... 1 MPa |
| Operating pressure | 0 ... 10 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [-::-] |
| Corrosion resistance classification CRC | 4 - Very high corrosion stress |
| PWIS conformity | VDMA24364 zone III |
| Protection class | IP65 in assembled condition |
| Product weight | 330 g |
| Mounting type | With through-hole and screw |
| Pilot air port 12 | G1/4 |
| Pneumatic connection, port 1 | G1/4 |
| Pneumatic connection, port 2 | Flange 1/4 with NAMUR connection |
| Pneumatic connection, port 3 | G1/4 |
| Materials note | Conforms to RoHS |
| Material of connecting plate | Aluminium (Ematal coated) |
| Material seals | NBR |