


sub-base VMPA14-FB-AP-4-1

Part number: 8074666

FESTO

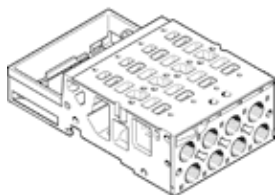

Data sheet

| Feature | Value |
|---|-------------------------|
| Width | 65.5 mm |
| Length | 107.3 mm |
| Grid dimension | 14.8 mm 14.9 mm |
| Max. number of valve positions | 4 |
| Operating pressure MPa | -0.09 ... 1 MPa |
| Operating pressure | -0.9 ... 10 bar |
| Pilot pressure MPa | 0.3 ... 0.8 MPa |
| Pilot pressure | 3 ... 8 bar |
| Corrosion resistance classification CRC | 0 - No corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -5 ... 50 °C |
| Product weight | 250 g |
| Pneumatic connection, port 2 | M7 G1/8 |
| Pneumatic connection, port 4 | M7 G1/8 |
| Materials note | Conforms to RoHS |
| Material of connecting plate | Aluminium die cast |