


manifold rail

VABM-P7-18M-G18-M5-4

Part number: 8076386

FESTO

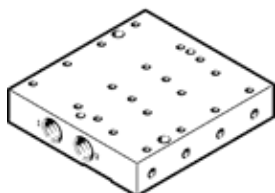

Data sheet

Feature	Value
Grid dimension	18 mm
Design structure	Connection direction on the side
Max. number of valve positions	4
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Max. tightening torque, valve mounting	0.6 Nm
Product weight	180 g
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	M5
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminium alloy