


manifold block

VABS-P4-20S-G38

Part number: 8087328

FESTO

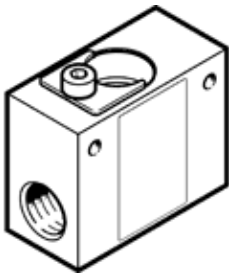

Data sheet

Feature	Value
Width	25 mm
Assembly position	Any
Special characteristics	Oxygen-compatible to DIN EN 1797
Design structure	Connection direction on the side
Max. number of valve positions	1
Operating pressure	0 ... 6 bar
Operating medium	Inert gases Air Oxygen
Note on operating and pilot medium	Lubricated operation not possible Maximum particle size 10 µm
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364 zone III
Storage temperature	-40 ... 80 °C
Medium temperature	5 ... 50 °C
Ambient temperature	5 ... 50 °C
Product weight	97 g
Mounting type	with through hole
Pneumatic connection, port 1	G3/8
Pneumatic connection, port 2	G3/8
Materials note	Conforms to RoHS
Material of connecting plate	Anodised wrought aluminium alloy