


axial kit EAMM-A-T42-60PA

Part number: 8091045
Product to be discontinued

FESTO

Type to be discontinued. Available until 2023. See Support Portal for alternative products.

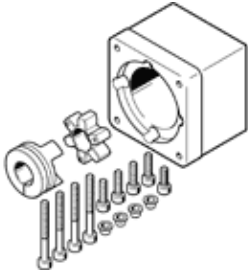

Data sheet

| Feature | Value |
|--------------------------|-----------------------|
| Nominal length | 49 mm |
| Assembly position | Any |
| Max. speed | 8,000 1/min |
| PWIS conformity | VDMA24364-B2-L |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Protection class | IP40 |
| Ambient temperature | -10 ... 60 °C |
| Mass moment of inertia | 3.2 kgmm ² |
| Transferable torque | 10 Nm |
| Product weight | 348 g |
| Interface code, actuator | T42 |
| Interface code, motor in | 60PA |
| Materials note | Conforms to RoHS |