


parallel kit EAMM-U-38-V25-35A-63

Part number: 8093286

FESTO

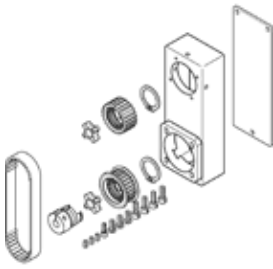

Data sheet

| Feature | Value |
|---------------------------|------------------------|
| Size | 38 |
| Centre-to-centre distance | 63 mm |
| Assembly position | Any |
| Gear unit ratio | 1:1 |
| Max. speed | 3,600 1/min |
| PWIS conformity | VDMA24364 zone III |
| Storage temperature | -20 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Protection class | IP40 |
| Ambient temperature | 0 ... 50 °C |
| Mass moment of inertia | 4.35 kgmm ² |
| No-load driving torque | 0.05 Nm |
| Transferable torque | 0.5 Nm |
| Product weight | 218 g |
| Interface code, actuator | V25 |
| Interface code, motor in | 23AB 35A |
| Materials note | Conforms to RoHS |