


# parallel kit EAMM-U-45-V32-42AB-63

Part number: 8095613

FESTO

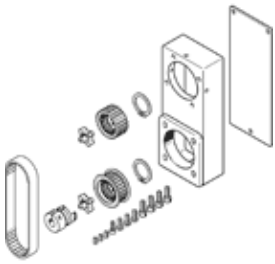

## Data sheet

| Feature                   | Value                  |
|---------------------------|------------------------|
| Size                      | 45                     |
| Centre-to-centre distance | 63 mm                  |
| Assembly position         | Any                    |
| Gear unit ratio           | 1:1                    |
| Max. speed                | 3,600 1/min            |
| PWIS conformity           | VDMA24364 zone III     |
| Storage temperature       | -20 ... 60 °C          |
| Relative air humidity     | 0 - 95 %               |
| Protection class          | IP40                   |
| Ambient temperature       | 0 ... 50 °C            |
| Mass moment of inertia    | 4.35 kgmm <sup>2</sup> |
| No-load driving torque    | 0.05 Nm                |
| Transferable torque       | 1 Nm                   |
| Product weight            | 242 g                  |
| Interface code, actuator  | V32                    |
| Interface code, motor in  | 42AB                   |
| Materials note            | Conforms to RoHS       |