


connecting plate VABS-B14-T-FG14

Part number: 8098884

FESTO

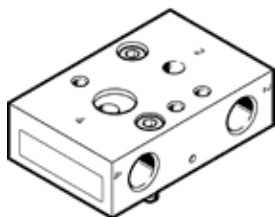

Data sheet

Feature	Value
Assembly position	Any
Design structure	Connection direction upwards
Operating pressure	1.5 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364 zone III
Storage temperature	-20 ... 60 °C
Medium temperature	-20 ... 60 °C
Ambient temperature	-20 ... 60 °C
Product weight	192 g
Mounting type	with through hole
Pneumatic connection, port 2	Flange 1/4 with NAMUR connection G1/4
Pneumatic connection, port 4	Flange 1/4 with NAMUR connection G1/4
Materials note	Conforms to RoHS
Material of connecting plate	Wrought Aluminium alloy