


# Exhaust plate

## VABF-B14-M3-N14

Part number: 8099627

FESTO

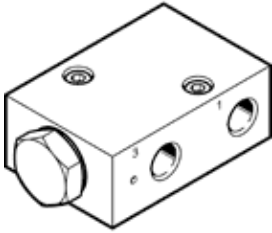

### Data sheet

Feature	Value
Assembly position	Any
Operating pressure	1.5 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364 zone III
Storage temperature	-20 ... 80 °C
Medium temperature	-20 ... 80 °C
Ambient temperature	-20 ... 80 °C
Product weight	280.5 g
Mounting type	with through hole
Pneumatic connection, port 1	1/4 NPT
Pneumatic connection, port 2	Flange 1/4 with NAMUR connection
Pneumatic connection, port 4	Flange 1/4 with NAMUR connection 1/4 NPT
Materials note	Conforms to RoHS
Material regulator housing	Wrought Aluminium alloy