


connecting plate VABS-B14-T-FN14

Part number: 8099628

FESTO

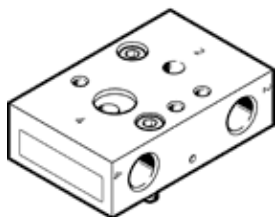

Data sheet

| Feature | Value |
|---|--|
| Assembly position | Any |
| Design structure | Connection direction upwards |
| Operating pressure | 1.5 ... 10 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364 zone III |
| Storage temperature | -20 ... 60 °C |
| Medium temperature | -20 ... 60 °C |
| Ambient temperature | -20 ... 60 °C |
| Product weight | 192 g |
| Mounting type | with through hole |
| Pneumatic connection, port 2 | Flange 1/4 with NAMUR connection 1/4 NPT |
| Pneumatic connection, port 4 | Flange 1/4 with NAMUR connection 1/4 NPT |
| Materials note | Conforms to RoHS |
| Material of connecting plate | Wrought Aluminium alloy |