


axial kit
EAMM-A-D40-58AA
Part number: 8105928

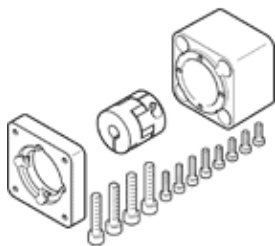

Data sheet

Feature	Value
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	12.5 Nm
Product weight	354 g
Interface code, actuator	D40
Interface code, motor in	58AA
Materials note	Conforms to RoHS