


# terminal strip NECC-L8G5-C1

Part number: 8106756

FESTO

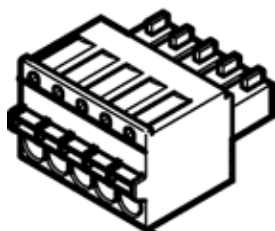

## Data sheet

Feature	Value
Cable outlet	Straight
Product weight	3.8 g
Container size	1
Electrical connection 1, design	Angular
Electrical connection 1, connection type	Plug socket
Electrical connection 1, connection technology	Manufactured by Assmann WSW components GmbH
Electrical connection 1, number of pins/wires	5
Electrical connection 1, type of mounting	Plug-in
Electrical connection 2, connection technology	Cage clamp terminal
Operating voltage range DC	0 ... 300 V
Acceptable current load at 40°C	8 A
Surge strength	1.6 kV
Shielding	No
Nominal conductor cross section (AWG)	AWG28 - 16
Protection class	IP20
Note on degree of protection	in assembled condition
Ambient temperature	-40 ... 115 °C
PWIS conformity	VDMA24364 zone III
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	1 - Low corrosion stress
Material housing	PA
Housing colour	Black