


Gripper jaw DHAS-GG-B18-16-A1

Part number: 8119108

FESTO

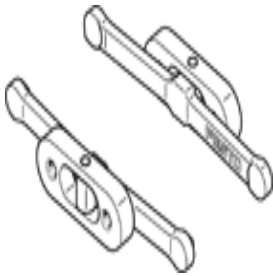

Data sheet

Feature	Value
Size	16 mm
Assembly position	Any
Design	For microwell plates
Vibration resistance	Transport application test at severity level 2 in accordance with FN 942017-4 and EN 60068-2-6
Shock resistance	Shock test with severity level 2 in accordance with FN 942017-5 and EN 60068-2-27
Corrosion resistance classification CRC	4 - Very high corrosion stress
PWIS conformity	VDMA24364-B2-L
Storage temperature	-20 ... 70 °C
Relative air humidity	0 - 100 %
Ambient temperature	0 ... 40 °C
Product weight	24.4 g
Mounting type	With female thread M3
Materials note	Conforms to RoHS
Material gripper jaws	High alloy steel, non-corrosive
Material cylindrical dowel pin	Spring steel