


manifold block-SET VABS-C12-6-S

Part number: 8122790

FESTO

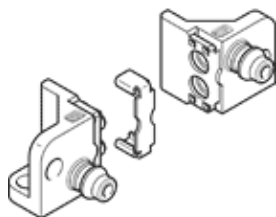

Data sheet

| Feature | Value |
|------------------------------------|--|
| Width | 13 mm |
| Assembly position | Any |
| Design structure | Connection direction on the side |
| Max. number of valve positions | Versions to customer requirements possible |
| Operating pressure MPa | -0.1 ... 0.7 MPa |
| Operating pressure | -1 ... 7 bar |
| Operating medium | Compressed air to ISO 8573-1:2010 [6:4:1] |
| Note on operating and pilot medium | Maximum particle size: 5 µm |
| PWIS conformity | VDMA24364 zone III |
| Ambient temperature | 5 ... 50 °C |
| Product weight | 3 g |
| Mounting type | with through hole |
| Pneumatic connection, port 2 | For tubing internal diameter 4 mm |
| Materials note | Conforms to RoHS |
| Material manifold | PBT |