


# manifold block VABS-C12-6-B-M3

Part number: 8122793

FESTO

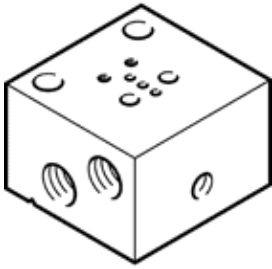

## Data sheet

| Feature                            | Value                                     |
|------------------------------------|---|
| Width                              | 20 mm                                     |
| Assembly position                  | Any                                       |
| Design structure                   | Connection direction underneath           |
| Max. number of valve positions     | 1   |
| Operating pressure MPa             | -0.1 ... 0.7 MPa                          |
| Operating pressure                 | -1 ... 7 bar                              |
| Operating medium                   | Compressed air to ISO 8573-1:2010 [6:4:1] |
| Note on operating and pilot medium | Maximum particle size: 5 µm               |
| PWIS conformity                    | VDMA24364 zone III                        |
| Ambient temperature                | 5 ... 50 °C                               |
| Product weight                     | 13.5 g                                    |
| Mounting type                      | with through hole                         |
| Pneumatic connection, port 1       | M5  |
| Pneumatic connection, port 2       | M3  |
| Pneumatic connection, port 3       | M5  |
| Materials note                     | Conforms to RoHS                          |
| Material manifold                  | Wrought Aluminium alloy                   |