


# sub-base VABS-K2-10B-16-U14-P

Part number: 8122826

FESTO

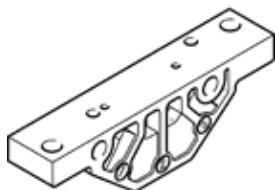

## Data sheet

Feature	Value
Size	10
Nominal size	1.6 mm
Fluid connection	Female thread 1/4-28 UNF-2B
Assembly position	Any
Design structure	Connection direction underneath
Max. number of valve positions	1
Flow direction	non reversible
Operating medium	Fluid media Gaseous media
Note on operating and pilot medium	Observe resistance of materials that come into contact with media
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364 zone III
Storage temperature	-20 ... 70 °C
Medium temperature	0 ... 50 °C
Ambient temperature	0 ... 50 °C
Max. tightening torque, valve mounting	0.2 Nm
Product weight	7 g
Mounting method for sub-base	with through hole
Mounting method for valve	with internal (female) thread
Materials note	Conforms to RoHS
Material of connecting plate	PEEK