


sub-base VABS-K2-10S-16-M6-P

Part number: 8122827

FESTO

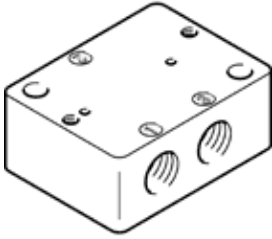

Data sheet

Feature	Value
Size	10
Nominal size	1.6 mm
Fluid connection	Female thread M6
Assembly position	Any
Design structure	Connection direction on the side
Max. number of valve positions	1
Flow direction	non reversible
Operating medium	Fluid media Gaseous media
Note on operating and pilot medium	Observe resistance of materials that come into contact with media
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364 zone III
Storage temperature	-20 ... 70 °C
Medium temperature	0 ... 50 °C
Ambient temperature	0 ... 50 °C
Max. tightening torque, valve mounting	0.2 Nm
Product weight	7 g
Mounting method for sub-base	with through hole
Mounting method for valve	with internal (female) thread
Materials note	Conforms to RoHS
Material of connecting plate	PEEK