


# connecting cable

## NEBV-HPG2-PN-0.3-N-LE2

Part number: 8122832

FESTO

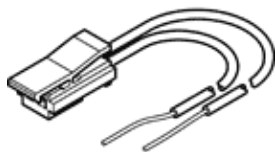

## Data sheet

Feature	Value
Max. number of solenoid coils	1
Cable identification	Without inscription label holder
Assembly position	Any
Product weight	2 g
Electrical connection 1, function	Field device side Switching output
Electrical connection 1, design	Angular
Electrical connection 1, connection type	Cable with socket
Electrical connection 1, cable outlet	Straight
Electrical connection 1, connection technology	Plug pattern HP
Electrical connection 1, number of pins/wires	2
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Push-pull with interlock against unintentional pulling
Electrical connection 2, function	Power supply Controller side
Electrical connection 2, connection type	2 single wires
Electrical connection 2, connection technology	Open end
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
Operating voltage range DC	0 ... 24 V
Shielding	No
Note on operation	Operate only with external power reduction
Cable length	0.3 m
Cable attribute	For static applications
Bending radius, fixed cable installation	≥ 11 mm
Cable diameter	0.96 mm
Protection class	IP40
Ambient temperature	0 ... 50 °C
Storage temperature	-20 ... 70 °C
PWIS conformity	VDMA24364 zone III
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	0 - No corrosion stress
Material housing	PEEK
Housing colour	Grey
Material insulation	PVC