 



# valve

## VOFC-LT-M32C-M-FN14-FN

Part number: 8122932

FESTO

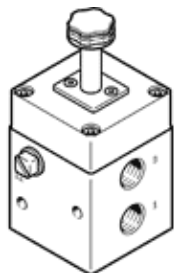

### Data sheet

Feature	Value
Standard nominal flow rate	601 l/min
Operating pressure MPa	0 ... 0.8 MPa
Operating pressure	0 ... 8 bar
Protection class	IP65
Certificate issuing department	TÜV 968/V 1251.00/21
Safety function	Safe venting
Safety Integrity Level (SIL)	Product can be used in SRP/CS up to SIL 3 (high demand) bis SIL 3 Low Demand mode
Note on operating pressure	0 - 0.8 MPa with external pilot air
Corrosion resistance classification CRC	4 - Very high corrosion stress
PWIS conformity	VDMA24364 zone III
Materials note	Conforms to RoHS