


manifold block

VABS-S7-RB-B-G14-A-R12

Part number: 8141067
New

FESTO

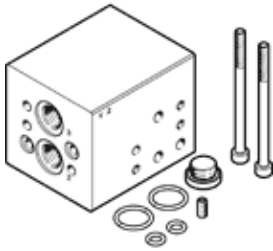

Data sheet

Feature	Value
Assembly position	Any
Pilot air supply	external Internal
Operating pressure MPa	0 ... 1 MPa
Operating pressure	0 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:-:-]
Corrosion resistance classification CRC	4 - Very high corrosion stress
PWIS conformity	VDMA24364 zone III
Protection class	IP65 in assembled condition
Product weight	750 g
Mounting type	with through hole
Pilot air port 12	G1/4
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	Flange 1/4 with NAMUR connection
Pneumatic connection, port 3	G1/4
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium (Ematal coated)
Material seals	NBR