


power supply unit CACN-3A-1-20-G2

Part number: 8149582

FESTO

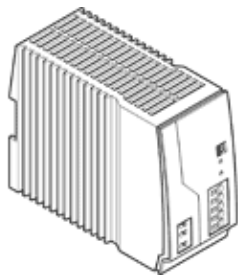

Data sheet

Feature	Value
Width	68 mm
Height	130 mm
Length	160 mm
Assembly position	Free convection
Primary supply	Single-phase
Input current	2,4 - 5,6 A
Nominal output voltage DC	24 V
Nominal output current	20 A
Input voltage range AC	100 ... 240 V
Power failure buffering	15 ms
Line frequency	45 ... 65 Hz
Authorisation	c UL us - Listed (OL)
CE mark (see declaration of conformity)	to EU directive for EMC to EU directive low-voltage devices
PWIS conformity	VDMA24364 zone III
Storage temperature	-40 ... 85 °C
Relative air humidity	95 %
Protection class	IP20
Ambient temperature	-25 ... 70 °C
Product weight	1,669 g
Mounting type	with top-hat rail
Materials note	Conforms to RoHS