


axial kit EAMM-A-D80-150A

Part number: 8157273

FESTO

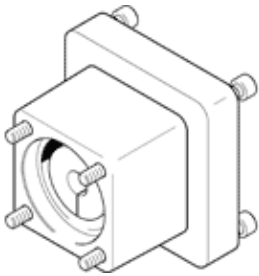

Data sheet

| Feature | Value |
|--------------------------|------------------|
| Assembly position | Any |
| PWIS conformity | VDMA24364-B2-L |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Protection class | IP40 |
| Ambient temperature | -10 ... 60 °C |
| Transferable torque | 60 Nm |
| Product weight | 3,058 g |
| Interface code, actuator | D80B |
| Interface code, motor in | 140A 150A |
| Materials note | Conforms to RoHS |