


axial kit

EAMM-A-D80-150A-S1

Part number: 8157274

FESTO

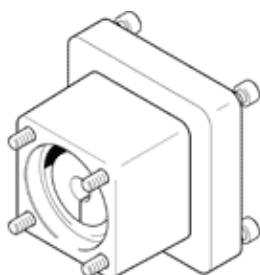

Data sheet

Feature	Value
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP65
Ambient temperature	-10 ... 60 °C
Transferable torque	60 Nm
Product weight	3,068 g
Interface code, actuator	D80B
Interface code, motor in	140A 150A
Materials note	Conforms to RoHS