


# axial kit EAMM-A-N80-150A

Part number: 8157277

FESTO

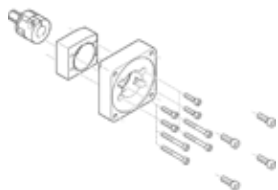

## Data sheet

| Feature                  | Value            |
|--------------------------|------------------|
| Assembly position        | Any              |
| PWIS conformity          | VDMA24364-B2-L   |
| Storage temperature      | -25 ... 60 °C    |
| Relative air humidity    | 0 - 95 %         |
| Protection class         | IP40             |
| Ambient temperature      | -10 ... 60 °C    |
| Transferable torque      | 47 Nm            |
| Product weight           | 2,407 g          |
| Interface code, actuator | N80              |
| Interface code, motor in | 140A<br>150A     |
| Materials note           | Conforms to RoHS |