


# sub-base VMPA-FB-AP-1-EMM-P5-SL

Part number: 8161060

FESTO

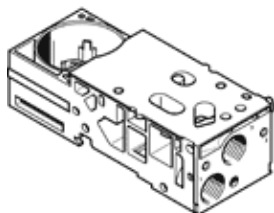

## Data sheet

Feature	Value
Width	42 mm
Length	107.3 mm
Grid dimension	41 mm
Max. number of valve positions	4
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364 zone III
Storage temperature	-20 ... 60 °C
Ambient temperature	-5 ... 50 °C
Product weight	175 g
Pneumatic connection, port 1	G1/4
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium die cast