


# Short AV-8-4-C

Part number: 9336

FESTO

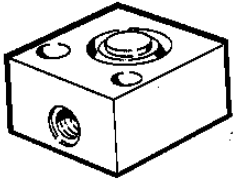

## Datasheet

Feature	Value
Mode of operation	Single, pushing
Shape piston	Round
Shape of piston rod	Round
Sensing type	None
Type of cushioning	None
Protection against torsion	None
Piston, nominal size	8
Stroke	4 mm
Piston rod diameter	4 mm
End of piston rod	III
Operating pressure min.	2 bar
Operating pressure max.	10 bar
Minimum ambient temperature	-20 °C
Maximum ambient temperature	80 °C
Material of barrel/housing	Aluminium
Air connection type cover cap	Female thread
EE Connecting thread for end cap	M 5
Effective force (theor.) at 6 bar, adv	.26 N
Spring return force min.	3,8 N
Spring return force max.	5 N
Air consumpt.at 6 bar per advance stro	ke0,0014 l
Medium	Compressed air, filtered