


adapter AD-1/4NPT-G1/4-I

Part number: 9625

FESTO

Female thread one side, male thread on the other.

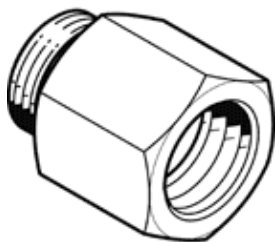

Data sheet

Feature	Value
Nominal size	7.95 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Max. tightening torque, pneumatic connection 1	12 Nm
Max. tightening torque, pneumatic connection 2	11 Nm
Product weight	21 g
Pneumatic connection, port 1	Male thread 1/4 NPT
Pneumatic connection, port 2	Female thread 1/4
Materials note	Conforms to RoHS
Material seals	PVC
Material housing	steel, galvanized