


Indicating plug MFL-24DC/AC

Part number: 10004

FESTO

With light-emitting diode(LED)

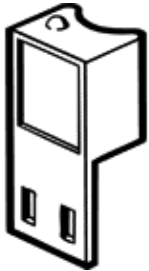

Data sheet

Feature	Value
Product weight	15 g
Electrical connection	Plug pattern type B to EN 175301-803 to industry standard (11 mm)
Nominal operating voltage DC	24 V
Nominal operating voltage, AC	24 V
Line frequency	0 ... 60 Hz
Permissible voltage fluctuation	+/- 15 %
Protection class	IP65 to IEC 60529
Ambient temperature	-20 ... 60 °C
PWIS conformity	VDMA24364-B2-L
Material housing	PA6 reinforced