

 

Stem actuated micro valve

SO-3-PK-3-B

Part number: 10403

FESTO

With barbed fitting connection for 3 mm ID tubing, normally open.
This type is suitable for vacuum.

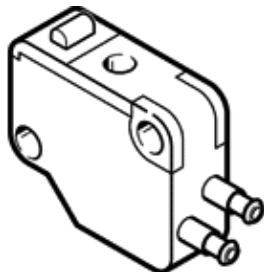

Data sheet

Feature	Value
Valve function	3/2 open, monostable
Type of actuation	mechanical
Standard nominal flow rate	60 l/min
Working pressure	-0.95 ... 8 bar
Type of reset	mechanical spring
Nominal size	1.8 mm
Type of piloting	direct
PWIS conformity	VDMA24364 zone III
Ambient temperature	-10 ... 60 °C
Actuating force	6 N
Product weight	7 g
Mounting type	with through hole
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Material housing	Brass POM