


Shock absorber DYSR-16-20-Y5-T

Part number: 1138645

FESTO

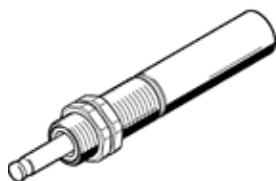

Data sheet

Feature	Value
Size	16
Stroke	20 mm
Cushioning	adjustable
Assembly position	Any
Position detection	No
Max. impact speed	3 m/s
Reset time short	0.3 s
Reset time long	1 s
Mode of operation	single-acting pushing action
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-10 ... 80 °C
Cushioning length	20 mm
Max. stop force	1,600 N
Max. energy consumption per stroke	32 J
Max. energy consumption per hour	100,000 J
Max. residual energy	0.16 J
Reset force	5.4 N
Product weight	250 g
Mounting type	with lock nut
Materials note	Conforms to RoHS
Material seals	NBR
Material housing	steel, galvanized
Material piston rod	High alloy steel, hardened