

 

# Clamping module

## EV-15/40-4

Part number: 13289

FESTO

With reset function

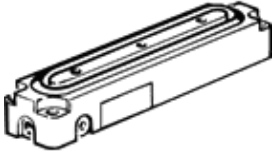

## Data sheet

Feature	Value
Stroke	4 mm
Clamping surface	15x40
Assembly position	Any
Mode of operation	single-acting
Working pressure	2 ... 6 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364-B1/B2-L
RSBP classification to CD-0033	F5
Ambient temperature	-20 ... 40 °C
Product weight	45 g
Mounting type	with through hole
Pneumatic connection	M5
Material housing	Aluminum die cast
Material membrane	TPE-U(PU)