


Push-in/threaded L-fitting NPQP-LQ-R38-Q10-FD-P10

Part number: 133068

FESTO

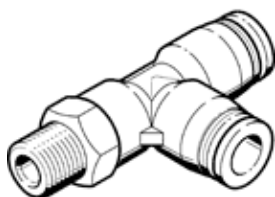

Data sheet

Feature	Value
Size	Standard
Nominal size	5.8 mm
Design	L-shape, additional push-in connector, lengthwise
Container size	10
Design structure	Push/pull principle
Temperature dependent working pressure	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	4 - Very high corrosion stress
PWIS conformity	VDMA24364 zone III
Food-safe	See Supplementary material information
Ambient temperature	-20 ... 60 °C
Product weight	19 g
Mounting type	External hex A/F 17
Pneumatic connection, port 1	Male thread R3/8
Pneumatic connection, port 2	For tubing outside diameter 10 mm
Materials note	Conforms to RoHS
Material housing	PP
Material of tube retaining claw	High alloy steel, non-corrosive