


# Braking resistance CACR-LE2-100-W500

Part number: 1336615

FESTO

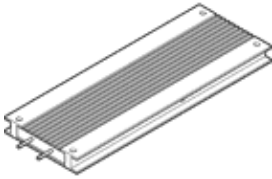

## Data sheet

Feature	Value
Size	500
Assembly position	Free convection Vertical
Pulse energy, braking resistor at 380 V	2,000 Ws
Pulse energy, braking resistor at 780 V	1,800 Ws
Performance at 35% duty cycle and 20°C	500 W
Rated capacity, braking resistance	200 W
Rated output, braking resistor at 380 V	150 W
Rated output, braking resistor at 780 V	120 W
Resistance value	100 Ohm
Authorization	c CSA us (OL) c UL us - Recognized (OL)
PWIS conformity	VDMA24364 zone III
Protection class	IP65
Ambient temperature	0 ... 50 °C
Product weight	550 g
Mounting type	with through hole with accessories Optional
Materials note	Conforms to RoHS