


# Multi-tube connector KM-22-B

Part number: 13694

FESTO

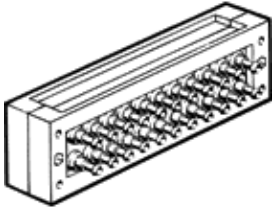

## Data sheet

Feature	Value
Nominal size	4 mm
Container size	1
Operating pressure MPa	-0.095 ... 0.8 MPa
Working pressure	-0.95 ... 8 bar
Operating pressure	-13.775 ... 116 psi
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B2-L
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Max. number of connections	22
Pneumatic connection	For tubing outside diameter 3 mm For tubing outside diameter 4 mm For tubing outside diameter 6 mm
Materials note	Conforms to RoHS