


# Coupling

## EAMD-67-51-32-32X32-U

Part number: 1379269

FESTO

drive component, which transmits the rotary motion of a stepper or servo motor

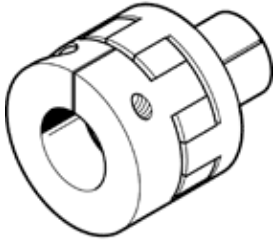

### Data sheet

Feature	Value
Holder diameter 1	32 mm
Holder diameter 2	32 mm
Size	67
Nominal length	51 mm
Assembly position	Any
Max. speed	4,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	374 kgmm <sup>2</sup>
Transferable torque	192 Nm
Product weight	717 g
Materials note	Conforms to RoHS