

 

# Finger lever valve

## TH/O-3-PK-3

Part number: 13794

FESTO

With barbed fitting connection for 3mm ID tubing. Depending on the choice of connections, normally-open or normally-closed function.

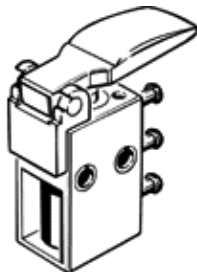

## Data sheet

| Feature                             | Value  |
|-------------------------------------|--|
| Valve function                      | 3/2 open/closed, monostable                              |
| Standard nominal flow rate          | 80 l/min   |
| Working pressure                    | 0 ... 8 bar  |
| Design structure                    | Piston seat  |
| Nominal size                        | 2.5 mm   |
| Type of piloting                    | direct   |
| Operating medium                    | Compressed air in accordance with ISO8573-1:2010 [-:--:] |
| PWIS conformity                     | VDMA24364-B1/B2-L  |
| Ambient temperature                 | -10 ... 60 °C  |
| Actuating force for normally closed | 8 N  |
| Actuating force for normally open   | 6 N  |
| Product weight                      | 18 g   |
| Mounting type                       | with through hole  |
| Pneumatic connection, port 1        | PK-3   |
| Pneumatic connection, port 2        | PK-3   |
| Pneumatic connection, port 3        | PK-3   |
| Material seals                      | NBR  |
| Material housing                    | Plastic  |