


Suction cup complete VASB-55-1/4-PUR-B

Part number: 1396063

★ Core product range

FESTO

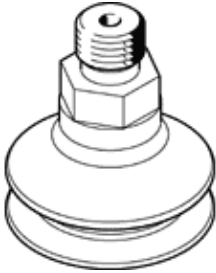

Data sheet

Feature	Value
Suction cup height compensator	20 mm
Nominal size	4 mm
suction cup diameter	55 mm
suction cup volume	30.4 cm ³
Effective suction diameter	44.7 mm
Position of connection	on top
Assembly position	Any
Suction cup shape	Round, bellows 1.5 conv
Operating pressure MPa	-0.095 ... 0 MPa
Working pressure	-0.95 ... 0 bar
Operating pressure	-13.775 ... 0 psi
Nominal operating pressure	-0.07 MPa
Nominal working pressure	-0.7 bar
Nominal operating pressure (psi)	-10.15 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-A1-L
Ambient temperature	-20 ... 60 °C
Retention force at nominal operating pressure	110 N
Product weight	39 g
Mounting type	Via vacuum port
Vacuum connection	G1/4
Color	blue
Shore hardness	60 +/- 5
Material of threaded plug	Zinc die-casting
Materials note	Conforms to RoHS
Material suction cup	PUR