 



Programming cable NEBC-U1G4-K-1.8-N-U2G4

Part number: 1501332

FESTO

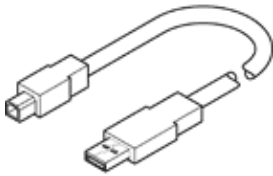

Data sheet

Feature	Value
Cable identification	Without inscription label holder
Assembly position	Any
Electrical connection 1	Straight plug, USB 2.0 type A, 4-pin
Electrical connection 1, function	Field device side
Electrical connection 1, design	Angular
Electrical connection 1, connection type	Plug
Electrical connection 1, cable outlet	Straight
Electrical connection 1, connection technology	USB 2.0 type B
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	4
Electrical connection 2	Straight plug, USB 2.0 type B, 4-pin
Electrical connection 2, function	Controller side
Electrical connection 2, design	Angular
Electrical connection 2, connection type	Plug
Electrical connection 2, cable outlet	Straight
Electrical connection 2, connection technology	USB 2.0 Typ A
Electrical connection 2, number of pins/wires	4
Electrical connection 2, occupied pins/wires	4
Cable length	1.8 m
Cable attribute	Standard
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	0 - No corrosion stress