


Flow control valve GRLO-10-UNF-B

Part number: 151569

FESTO

Without check function, with swivel joint.

This product is only available if ordered from the Festo Corporation, USA.

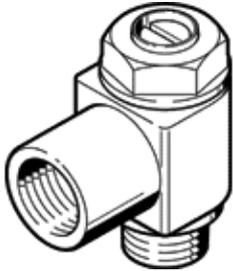

Data sheet

Feature	Value
Valve function	Throttle function
Pneumatic connection, port 1	UNF10-32
Pneumatic connection, port 2	UNF10-32
Adjusting element	Slotted head screw
Mounting type	Threaded
Working pressure	0 ... 10 bar
Ambient temperature	-10 ... 60 °C
Operating medium	Filtered, unlubricated compressed air, 40 µm filtration Filtered, lubricated compressed air, 40 µm filtration
Medium temperature	-10 ... 60 °C