


Guide unit FEN-5/16"-3/8"- -KF

Part number: 151730

FESTO

with recirculating ball bearing guide, serves for protection against rotation, provides a high accuracy of guidance.

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

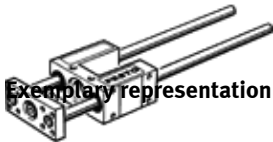

Data sheet

Feature	Value
Size	5/16"
Stroke	0.04 ... 10 "
Assembly position	Any
Guide	Recirculating ball bearing guide
Design structure	Guide
Ambient temperature	-4 ... 176 °F
Displacement force	15 N
Additional weight per 10 mm stroke	11 g
Basic weight for 0 mm stroke	300 g
Mounting type	with internal (female) thread
Material of guide component	Heat-treatment steel
Material housing	Aluminum die cast