 



Clamping module EV-10/30-3

Part number: 151993

FESTO

With reset function

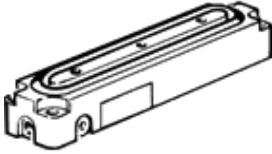

Data sheet

Feature	Value
Stroke	3 mm
Clamping surface	10x30
Assembly position	Any
Mode of operation	single-acting
Working pressure	≤ 6 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364-B1/B2-L
RSBP classification to CD-0033	F5
Ambient temperature	-20 ... 40 °C
Product weight	20 g
Mounting type	with through hole
Pneumatic connection	M3
Material housing	Aluminum die cast
Material membrane	TPE-U(PU)