
 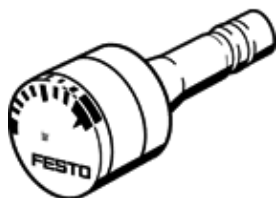


# Pressure gauge MA-15-10-QS-6

Part number: 153384

FESTO

With display unit in bar and psi.



## Data sheet

Feature	Value
Indicating range [bar]	0 ... 10 bar
Nominal size of pressure gauge	15
Design structure	Bourdon tube pressure gauge without measuring mechanism
Mounting type	Line installation
Operating medium	Inert gases Neutral fluids
Operating pressure MPa	0 ... 1 MPa
Working pressure	0 ... 10 bar
Operating pressure	0 ... 145 psi
Alternating load factor	0.66
Measurement accuracy class	5
Protection class	IP53
Medium temperature	-20 ... 60 °C
Ambient temperature	-20 ... 60 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Position of connection	Rear side central
Pneumatic connection	QS-6
Materials in contact with media	Brass
Material of threaded plug	Brass
Material housing	Steel
Material screen	PC
Housing color	Black
Product weight	10 g
Note on operating and pilot medium	No acetylene No oxygen